


MaxPlus Performance.
MaxPlus Power.

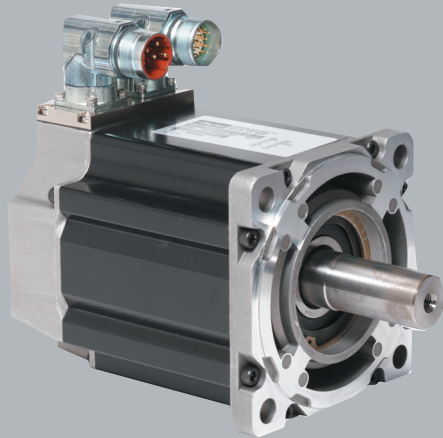

parkermotion.com


MaxPlusPlus.®

The newest,
highest-performing
servo motor
from Parker Hannifin.



Aerospace | **Automation** | Climate & Industrial Controls | Filtration | Fluid Connectors | Hydraulics | Instrumentation | Seal

MaxPlusPlus®

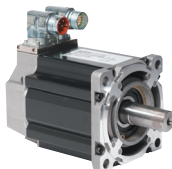

3-day delivery on select models*

- 5 frame sizes from 92 to 270mm.
- Segmented lamination design.
- Right-angle "rotatable" connections.
- 2000-line increment, resolver, single/multi-turn absolute and "Q" encoder feedback.
- Brushless construction.
- High-performance neodymium magnets.
- Thermistor protection.
- Full customizations.
- CE/UL compliant.



\$64 value

Register to WIN your Industrial Motor Drive Technology textbook by going to parkermotion.com/textbook.

parkermotion.com
800.358.9070



Parker Electromechanical
27 Seaview Blvd.
Port Washington, NY 11050
800.358.9070

* 3-day delivery starts August 15